

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300120339](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change C-Size Double-Ended Cordset, 19 Poles, Male (Straight) to Female (Straight), 18 & 22 AWG, PUR Cable, 5.0m (16.40') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Cordsets
Series	130012
Connector End A	Mini-Change
Connector End B	Mini-Change
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Protocol	FF
Region	Europe
Taxonomy	Circular Industrial Cordsets
Type	Double Ended
UPC	78678841461

Physical

Cable Diameter	11.43mm (.450")
Cable Length	5.0m (16.40')
Color - Cable Jacket	Black
Coupling Style	Threaded
Gender	Female-Male
Keyway	Single
LED Indicator	No
Material - Cable Jacket	PUR
Material - Connector Body	PVC
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - Plating Mating	Gold
Orientation	Straight to Straight
Poles	19
Temperature Range - Operating	-20° to +80°C
Wire Size AWG	18, 22
Wire/Cable Type	N/A

Electrical


Current - Maximum per Contact	2.0A, 3.0A
Voltage - Maximum	300V AC/DC

Material Info

Engineering Number	333030P80M050
--------------------	---------------

Reference - Drawing Numbers

Sales Drawing	SD-130012-004-001, SD-130012-015-001
---------------	--------------------------------------

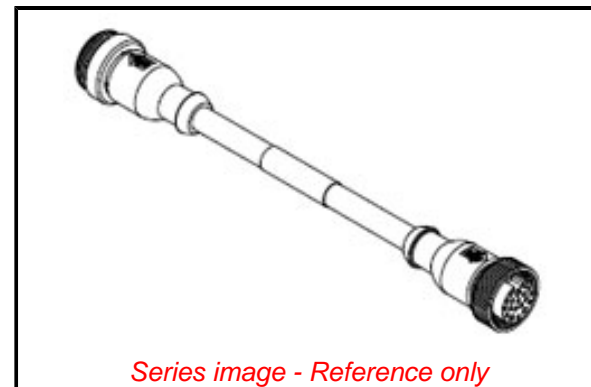

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130012 Series](#)