

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300340005](#)
Status: **Active**
Overview: [minichange_products](#)
Description: Mini-Change® Trunk Connector, Threaded, Single Keyway, Straight Female, 5 Poles

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family Field Attachable / Accessories
 Series [130034](#)
 IP Rating IP67
 Overview [minichange_products](#)
 Product Name Mini-Change®
 Type Field Attachable Connector

Physical

Cable Diameter N/A
 Coupling Type Internal Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Female
 Keyway Single
 Material - Connector Body PA
 Material - Contact Copper
 Material - Coupling Nut Nickel-plated Brass
 Material - Plating Mating n/a
 Orientation Straight
 Poles 5
 Temperature Range - Operating -25°C to +90°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 4A
 Voltage - Maximum 36V

Material Info

Old Part Number 1A5000-34DN

Reference - Drawing Numbers

Sales Drawing SD-130034-003

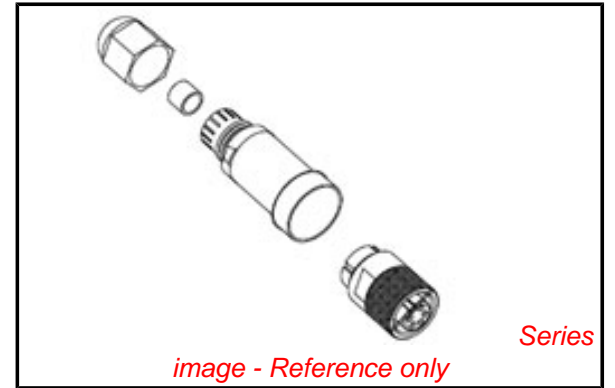

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Not Reviewed**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

130034Series