

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300360008](#)  
**Status:** **Active**  
**Overview:** [DeviceNet Solutions](#)  
**Description:** Mini-Change DeviceNet Passive 6 Junction

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E152210

**General**

Product Family Passive Distribution Boxes  
 Series [130036](#)  
 IP Rating IP67  
 NEMA Rating NEMA 6  
 Overview [DeviceNet Solutions](#)  
 Product Name DeviceNet, Mini-Change  
 UPC 78678829996

**Physical**

Bus I/O Mini-Change  
 Cable Connector Orientation N/A  
 Cable Length N/A  
 Home Run Cable Length N/A  
 Home Run Connector N/A  
 Home Run Interface N/A  
 Keyway Single  
 LED Indicator No  
 Material - Cable Jacket PVC  
 Material - Housing PBT  
 Material - Metal Copper Alloy  
 Material - Plating Mating Gold over Nickel  
 Orientation Side Mount  
 Poles 5  
 Poles (wired) 5  
 Ports 6  
 Temperature Range - Operating 0°C to +60°C  
 Wiring Configuration Single I/O per Port

**Electrical**


Current - Maximum per Contact 7.0A  
 Functional Wiring Parallel  
 Voltage - Maximum 120V AC/DC

**Material Info**

Engineering Number DN6000

**Reference - Drawing Numbers**

Sales Drawing SD-130036-002

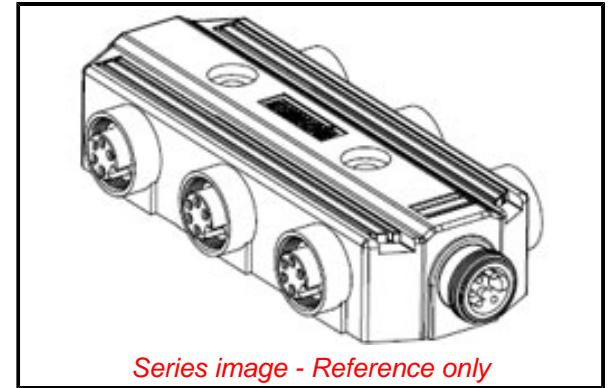

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**China RoHS**

**Search Parts in this Series**

[130036 Series](#)