

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300390097](#)
Status: **Active**
Overview: [Brad Mini-Change Connectors](#)
Description: Mini-Change Cord and Receptacle, DeviceNet Trunk Cable, 7/8" - 16 UN-2A Threads, Male-Female Straight, 5 Poles, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Receptacles
 Series [130039](#)
 IP Rating IP67
 Overview [Brad Mini-Change Connectors](#)
 Product Name DeviceNet Trunk, Mini-Change
 Taxonomy Circular Industrial Connectors
 Type Double Ended
 UPC 78678882935

Physical

Coupling Type Internal Thread
 Gender Male-Female
 Keyway Single
 Length 2.0m
 Material - Component Stainless Steel Type 303
 Mounting Thread Size 7/8" - 16 UN-2A
 Orientation Straight
 Panel Mount N/A
 Poles 5
 Temperature Range - Operating -20° to +80°C
 Wire Size AWG 16, 18
 Wire/Cable Type N/A

Electrical


Current - Maximum per Contact 4.0A
 Voltage - Maximum 300V AC/DC

Material Info

Engineering Number DN5210A-M020

Reference - Drawing Numbers

Sales Drawing SD-130039-005-001

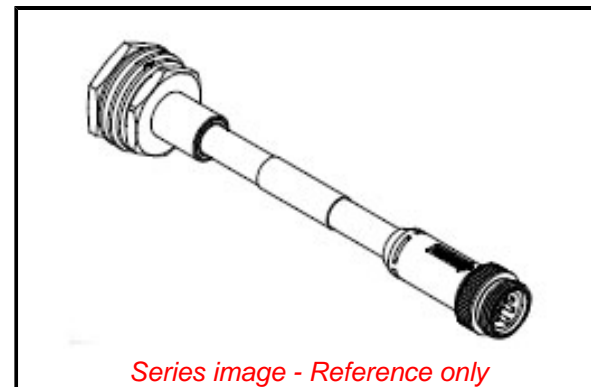

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130039 Series](#)