

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300630236](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower D-Size (1 3/8"-M35) Single-Ended Cordset, 4 Poles, Male (Straight) to Pigtail, 10 AWG, Black TPE Cable, 1.10m (3.61') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
 Series [130063](#)
 Connector End A BradPower D-Size (1 3/8"-M35)
 Connector End B Pigtail
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [BradPower Cordsets and Receptacles](#)
 Product Name BradPower D-Size
 Taxonomy Circular Industrial Cordsets
 Type Single Ended
 UPC 78172541526

Physical

Cable Diameter 13.46mm (.530")
 Cable Length 1.10m (3.61')
 Color - Cable Jacket Black
 Coupling Style Threaded
 Gender Male-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket TPE
 Material - Connector Body TPE
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold
 Net Weight 125.000/g
 Orientation Straight to Pigtail
 Poles 4
 Temperature Range - Operating -20° to +90°C
 Wire Size AWG 10
 Wire/Cable Type TC-ER

Electrical


Current - Maximum per Contact 32.0A
 Voltage - Maximum 600V AC/DC

Material Info

Engineering Number C04006K17M011G

Reference - Drawing Numbers

Sales Drawing SD-130063-097-001

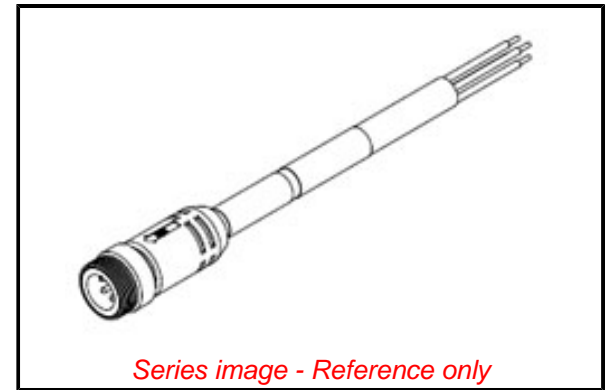

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[130063 Series](#)