

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300640187](#)
Status: **Active**
Overview: BradPower Cordsets and Receptacles
Description: BradPower D-Size (1 3/8"-M35) Double-Ended Cordset, 4 Poles, Male (Straight) to Female (Straight), 10 AWG, Gray PVC Cable, 2.0m (6.56') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Industrial Cordsets
 Series [130064](#)
 Connector End A BradPower D-Size (1 3/8"-M35)
 Connector End B BradPower D-Size (1 3/8"-M35)
 IP Rating IP67
 Material - Contact Copper Alloy
 Overview [BradPower Cordsets and Receptacles](#)
 Product Name BradPower D-Size
 Protocol EtherNet
 Region Europe
 Taxonomy Circular Industrial Cordsets
 Type Double Ended
 UPC 78678855746

Physical

Cable Diameter 5.08mm (.200")
 Cable Length 2.0m (6.56')
 Color - Cable Jacket Gray
 Coupling Style Threaded
 Gender Female-Male
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body TPE
 Material - Coupling Nut Anodized Aluminum
 Material - Plating Mating Gold
 Net Weight 1324.490/g
 Orientation Straight to Straight
 Poles 4
 Temperature Range - Operating -20° to +90°C
 Wire Size AWG 10
 Wire/Cable Type ST00W, TC-ER Direct Burial

Electrical


Current - Maximum per Contact 32.0A
 Voltage - Maximum 600V AC/DC

Material Info

Engineering Number CC4030A48M020

Reference - Drawing Numbers

Sales Drawing SD-130064-065-001

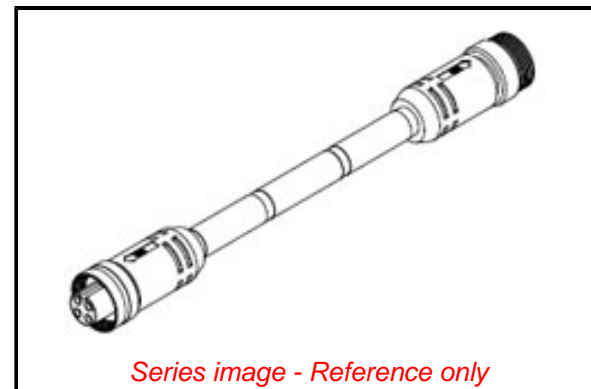

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_UKCA

- Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000410542_00_000.pdf

Search Parts in this Series

[130064 Series](#)

This document was generated on 10/20/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION