

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300830232](#)
Status: **Active**
Overview: [Reels - Woodhead](#)
Description: Woodhead POW-R-MITE Industrial Duty Cable Reel, 12/3 SOW, 15.24m (50.0') Cord Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR29921
 UL E22769

General

Product Family Electric Reels
 Series [130083](#)
 Cable Length N/A
 Comments Applications: Vertical Lift, Drag, Recovery and Horizontal Stretch with 10% Sag.
 Depth 0.34m (13.50")
 Duty Industrial
 Enclosure Rating NEMA 4
 Height 0.37m (14.50")
 NEMA Configuration N/A
 Overview [Reels - Woodhead](#)
 Product Name POW-R-MITE
 Taxonomy Electric Reels
 Type Cable Reel
 UPC 78678879242
 Width 244.35mm (9.620")


Physical

Cable Movement Ratchet Lock
 Cord Length 15.24m (50.0')
 Drum Lock Ratchet
 Guide Arm 5° increments over 270° Arc
 Material - Coating Powder Coating
 Material - Housing Cast Aluminum
 Mounting Style Rigid
 Net Weight 22679.618/g
 Number of Conductors 3
 Packaging Type Carton
 Primary Cord/Cable Entry 1" NPT
 Retraction Weight 1.8kg (4.0 lb)
 Wire Size AWG 12

Electrical

Bulb Included N/A
 Cord Type 12/3 SOW
 Current - Maximum per Contact 18.0A
 GFCI No
 Lamp Type N/A
 Lamp Wattage - Maximum N/A
 On/Off Switch N/A
 Voltage - Maximum 600V

Material Info

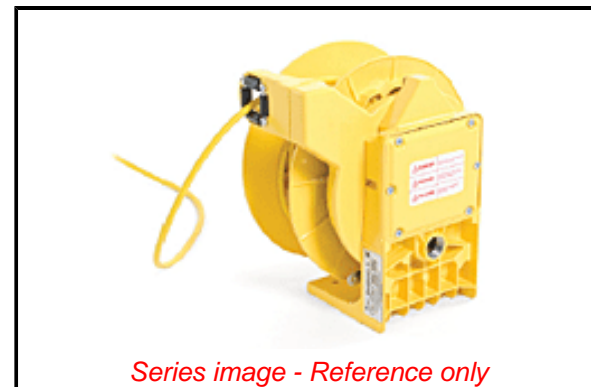

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[130083 Series](#)

Engineering Number

92433

Reference - Drawing Numbers

Sales Drawing

SD-130083-038-001

This document was generated on 10/11/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION