

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300830781](#)  
**Status:** **Active**  
**Overview:** [Reels - Woodhead](#)  
**Description:** Woodhead POW-R-MITE Industrial Duty Cable Reel, 12/3 SOW, 15.24m (50.0') Cord Length with 20A Connector and Ball Stop

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**

CSA                      LR29921  
 UL                        E22769

**General**


Product Family                      Electric Reels  
 Series                                  [130083](#)  
 Cable Length                        N/A  
 Comments                            Applications: Vertical Lift, Drag, Recovery and Horizontal Stretch with 10% Sag., Applications: Vertical Lift, Drag, Recovery and Horizontal Stretch with 10% Sag.  
 Depth                                  0.34m (13.50")  
 Duty                                    Industrial  
 Enclosure Rating                    NEMA 4  
 Exclude SD Check                    Yes  
 Height                                 0.37m (14.50")  
 NEMA Configuration                NEMA 5-20  
 Overview                              [Reels - Woodhead](#)  
 Product Literature Order No        987650-8062  
 Product Name                        POW-R-MITE  
 Type                                    Cable Reel  
 UPC                                    78678834666  
 Width                                 244.35mm (9.620")

**Physical**

Cable Movement                    Ratchet Lock  
 Cord Length                        15.24m (50.0')  
 Drum Lock                          Ratchet  
 Guide Arm                            5° increments over 270° Arc  
 Material - Coating                    Powder Coating  
 Material - Housing                   Cast Aluminum  
 Mounting Style                      Rigid  
 Net Weight                          22679.600/g  
 Number of Conductors               3  
 Number of Receptacles              1  
 Packaging Type                        Carton  
 Primary Cord/Cable Entry          1" NPT  
 Retraction Weight                    1.8kg (4.0 lb)  
 Wire Size AWG                        12

**Electrical**

Bulb Included                        N/A  
 Cord Type                            12/3 SOW  
 Current - Maximum per Contact    18.0A  
 GFCI                                  No  
 Lamp Type                            N/A  
 Lamp Wattage - Maximum          N/A

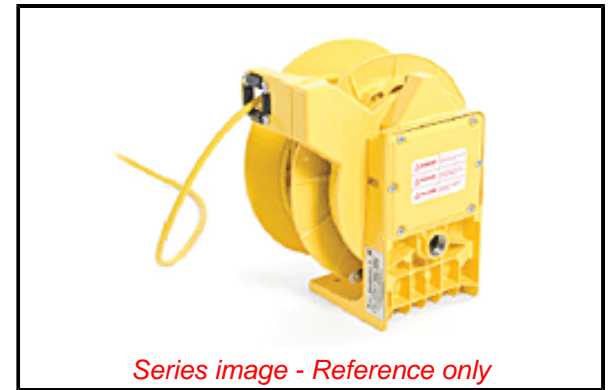

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130083 Series](#)

On/Off Switch  
Voltage - Maximum

N/A  
120V

**Material Info**

Engineering Number

92433-1533

This document was generated on 09/15/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**