

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300900015](#)  
**Status:** **Active**  
**Overview:** [Reels - Woodhead](#)  
**Description:** Woodhead Standard Duty Reel, 16/3 SJTOW Cord, 10.67m (35.0') Cord Length with 100W Incandescent Hand Lamp and Rubber Handle

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E22769

**General**

Product Family	Electric Reels
Series	<a href="#">130090</a>
Cable Length	0.457m (1.50')
Comments	Ratchet Lock (ON/OFF Switchable); NEMA 5-15 side Outlet
Depth	0.24m (9.59")
Duty	Standard
Enclosure Rating	NEMA 1
Height	0.32 (12.62")
NEMA Configuration	NEMA 5-15
Overview	<a href="#">Reels - Woodhead</a>
Product Name	Super-Safeway
Taxonomy	Electric Reels
Type	Cord Reel
UPC	78678875253
Width	13.06mm (5.160")

**Physical**


Cable Movement	Ratchet Lock
Cord Length	10.67m (35.0')
Drum Lock	Ratchet
Material - Coating	Powder Coating
Material - Housing	Steel
Mounting Style	Swinging
Number of Conductors	3
Packaging Type	Carton
Primary Cord/Cable Entry	N/A
Retraction Weight	0.9kg (2.0 lb)
Wire Size AWG	16

**Electrical**

Bulb Included	No
Cord Type	16/3 SJTOW
Current - Maximum per Contact	6.0A
GFCI	No
Lamp Type	Incandescent
Lamp Wattage - Maximum	100W
On/Off Switch	Yes
Voltage - Maximum	120V

**Material Info**

Engineering Number 963

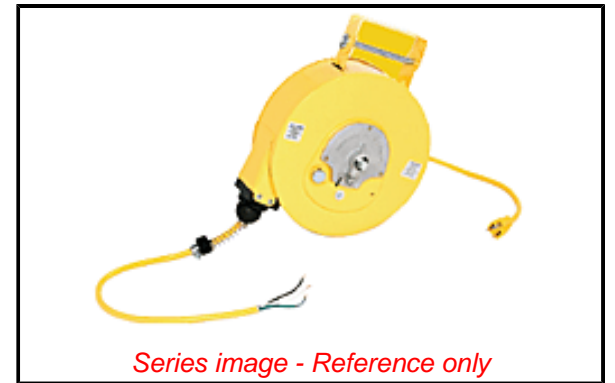

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130090](#) Series

This document was generated on 10/10/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**