


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940217](#)

**Status:** **Active**

**Overview:** [Support Grips](#)

**Description:** Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 31.75-37.85mm (1.250-1.490"), Approximate Break Strength 870.90kg (1920 lbs)

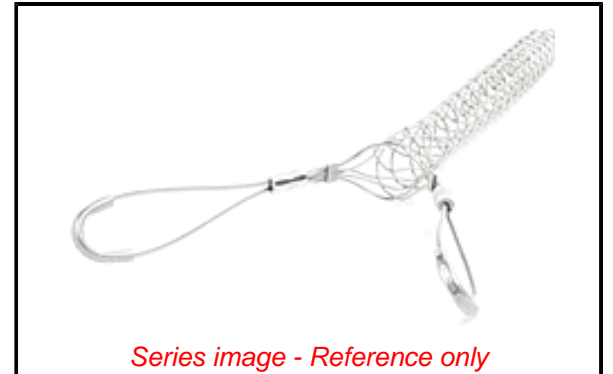

**Documents:**

[Packaging Specification PK-130227-004-001 \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Double
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835005

**Physical**

Approximate Break Strength	870.90kg (1920 lbs)
Bale Length	0.127m (5.00")
Body Style	Straight
Cable Diameter	31.75-37.85mm (1.250-1.490")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.406m (16.00")
Net Weight	486.120/g
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 35005

**Reference - Drawing Numbers**

Packaging Specification PK-130227-004-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Reviewed

Not Relevant

Not Contained

**Search Parts in this Series**

[130094 Series](#)