

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300940225**

Status: **Active**

Overview: [Support Grips](#)

Description: Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 1524.07kg (3360 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Double
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835009

Physical


Approximate Break Strength	1524.07kg (3360 lbs)
Bale Length	0.152m (6.00")
Body Style	Straight
Cable Diameter	63.50-75.95mm (2.500-2.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.61m (24.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35009

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

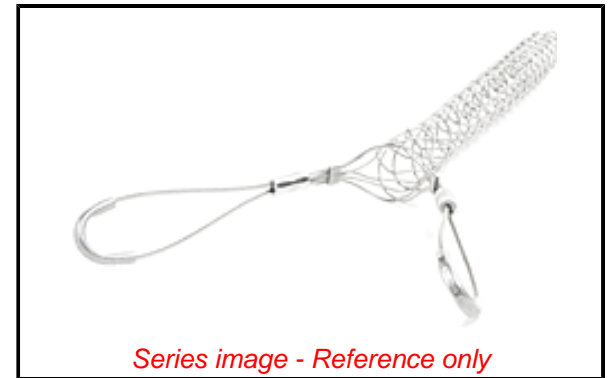

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

130094 Series