

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940230](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 12.70-15.49mm (.500-.610"), Approximate Break Strength 349.27kg (770 lbs)

Documents:


[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Standard Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835030
Physical	
Approximate Break Strength	349.27kg (770 lbs)
Bale Length	0.178m (7.00")
Body Style	Straight
Cable Diameter	12.70-15.49mm (.500-.610")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Net Weight	34.019/g
Number of Holes	N/A
Thread Size	N/A
Material Info	
Engineering Number	35030
Reference - Drawing Numbers	
Packaging Specification	PK-130227-004-001

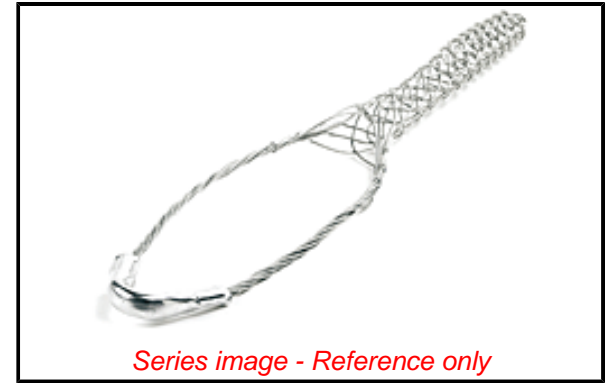

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

China RoHS

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION