

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940306](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double Eye, Split Lace, Single Weave, Cable Diameter 76.20-88.65mm (3.000-3.490"), Approximate Break Strength 2394.97kg (5280 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130094](#)
 Eye Type Double
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Standard Duty
 Taxonomy Cable Grips
 Type Support Grip
 UPC 78678835144


Physical
 Approximate Break Strength 2394.97kg (5280 lbs)
 Bale Length 0.203m (8.00")
 Body Style Straight
 Cable Diameter 76.20-88.65mm (3.000-3.490")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Non-magnetic Tin Bronze Wire
 Mesh Length 0.66m (26.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 35144

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

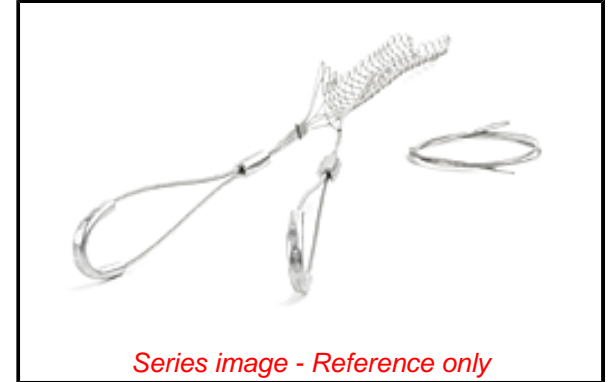

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION