

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **1300940312**  
**Status:** **Active**  
**Overview:** Support Grips  
**Description:** Standard Duty Support Grip, Single Eye, Split Lace, Single Weave, Cable Diameter 15.88-19.05mm (.625-.750"), Approximate Break Strength 435.45kg (960 lbs)

**Documents:**

[Packaging Specification PK-130227-004-001 \(PDF\)](#)    [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835166

**Physical**


Approximate Break Strength	435.45kg (960 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	15.88-19.05mm (.625-.750")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 35166

**Reference - Drawing Numbers**

Packaging Specification PK-130227-004-001

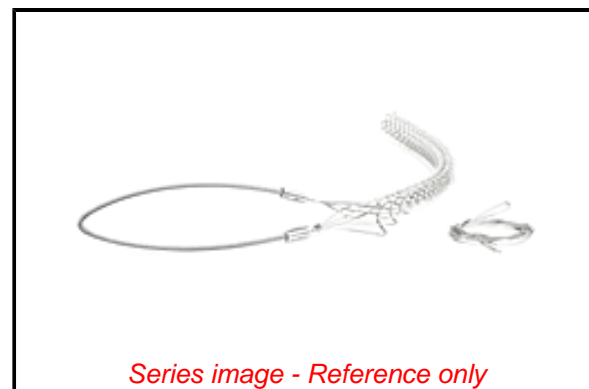

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**China RoHS**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS Not Reviewed

ELV Not Reviewed

RoHS Phthalates Not Reviewed

**Search Parts in this Series**

[130094 Series](#)