

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940332](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Offset Eye, Split Lace, Single Weave, Cable Diameter 15.88-19.05mm (.625-.750"), Approximate Break Strength 435.45kg (960 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130094](#)
 Eye Type Offset
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Standard Duty
 Taxonomy Cable Grips
 Type Support Grip
 UPC 78678835196

Physical


Approximate Break Strength 435.45kg (960 lbs)
 Bale Length 0.102m (4.00")
 Body Style Straight
 Cable Diameter 15.88-19.05mm (.625-.750")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Non-magnetic Tin Bronze Wire
 Mesh Length 0.279m (11.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 35196

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

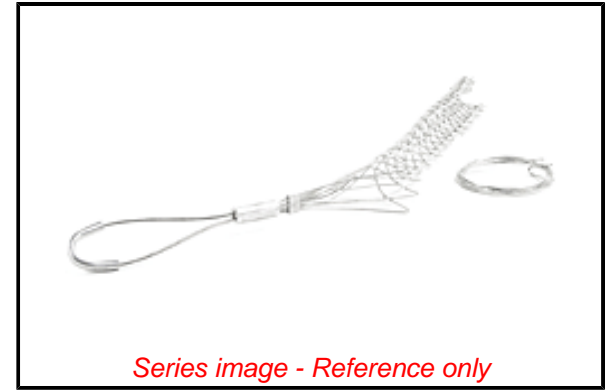

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[130094](#) Series