

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940384](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 88.90-101.35m (3.500-3.990"), Approximate Break Strength 2394.97kg (5280 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
Series [130094](#)
Eye Type Double
O-Ring N/A
Overview [Support Grips](#)
Product Name Standard Duty
Taxonomy Cable Grips
Type Support Grip
UPC 78678835280

Physical


Approximate Break Strength 2394.97kg (5280 lbs)
Bale Length 0.203m (8.00")
Body Style Straight
Cable Diameter 88.90-101.35mm (3.500-3.990")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.711m (28.00")
Number of Holes N/A
Thread Size N/A

Material Info

Engineering Number 35280

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

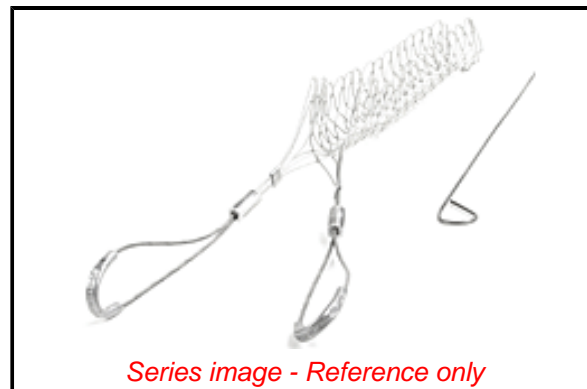

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION