

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940389](#)

Status: **Active**

Overview: Support Grips

Description: Standard Duty Support Grip, Single "U" Eye, Split Rod, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
Series [130094](#)
Eye Type Single
O-Ring N/A
Overview Support Grips
Product Name Standard Duty
Taxonomy Cable Grips
Type Support Grip
UPC 78678835287


Physical
Approximate Break Strength 598.74kg (1320 lbs)
Bale Length 0.203m (8.00")
Body Style Straight
Cable Diameter 19.05-25.15mm (.750-.990")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.356m (14.00")
Number of Holes N/A
Thread Size N/A

Material Info

Engineering Number 35287

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

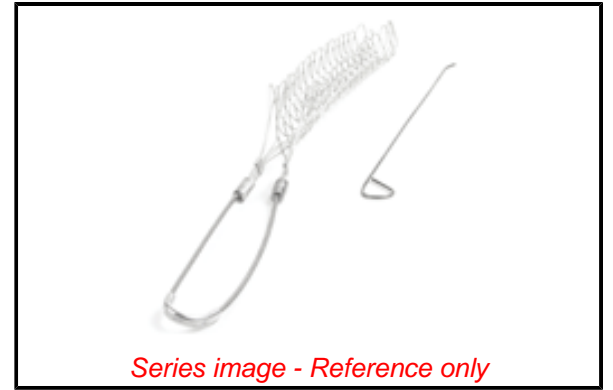

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130094 Series](#)