

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [1300940391](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Single "U" Eye, Split Rod, Single Weave, Cable Diameter 25.40-31.50mm (1.000-1.240"), Approximate Break Strength 762.04kg (1680 lbs)

**Documents:**

[Packaging Specification PK-130227-004-001 \(PDF\)](#)     [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA     LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Standard Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835288

**Physical**


Approximate Break Strength	762.04kg (1680 lbs)
Bale Length	0.229m (9.00")
Body Style	Straight
Cable Diameter	25.40-31.50mm (1.000-1.240")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.38m (15.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number     35288

**Reference - Drawing Numbers**

Packaging Specification     PK-130227-004-001

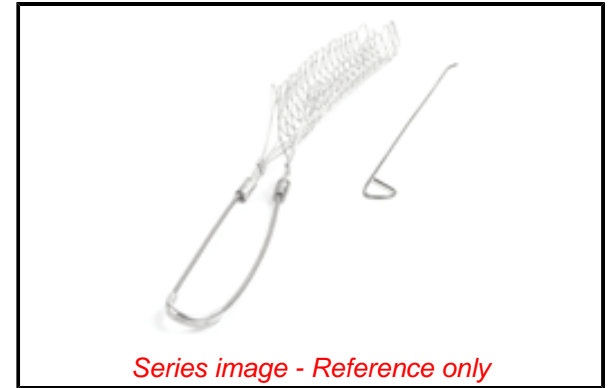

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[130094](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION