

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940406](#)
Status: **Active**
Overview: Support Grips
Description: Standard Duty Support Grip, Offset Eye, Split Rod, Single Weave, Cable Diameter 12.70-15.49mm (.500-.610"), Approximate Break Strength 349.27kg (770 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
Series [130094](#)
Eye Type Offset
O-Ring N/A
Overview [Support Grips](#)
Product Name Standard Duty
Taxonomy Cable Grips
Type Support Grip
UPC 78678835300

Physical


Approximate Break Strength 349.27kg (770 lbs)
Bale Length 0.102m (4.00")
Body Style Straight
Cable Diameter 12.70-15.49mm (.500-.610")
Color - Grommet N/A
Gender N/A
Material - Body N/A
Material - Grip Non-magnetic Tin Bronze Wire
Mesh Length 0.279m (11.00")
Number of Holes N/A
Thread Size N/A

Material Info

Engineering Number 35300

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

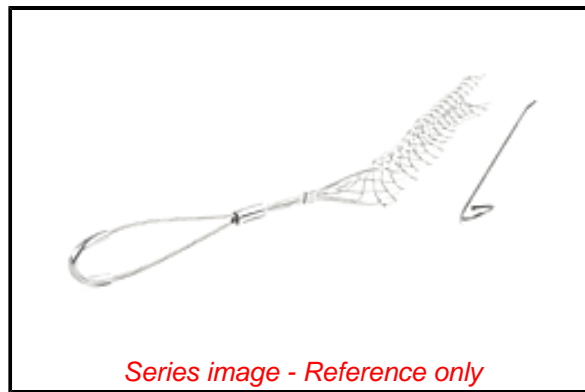

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130094 Series](#)