

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300940446**
Status: **Active**
Overview: Support Grips
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 38.10-50.55mm (1.500-1.990"), Approximate Break Strength 2140.96kg (4720 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	<u>130094</u>
Eye Type	Double
O-Ring	N/A
Overview	<u>Support Grips</u>
Product Name	Heavy Duty
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678835428

Physical


Approximate Break Strength	2140.96kg (4720 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	38.10-50.55mm (1.500-1.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.889m (35.00")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 35428

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

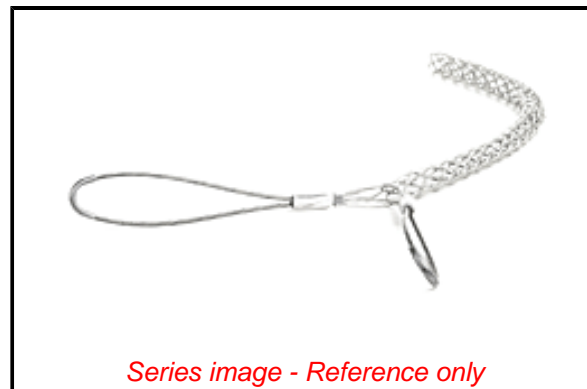

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[130094 Series](#)