

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **1300940472**
Status: **Active**
Overview: Support Grips
Description: Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 4572.21kg (10080 lbs)

Documents:

[Packaging Specification PK-130227-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series 130094
 Eye Type Double
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Heavy Duty
 Taxonomy Cable Grips
 Type Support Grip
 UPC 78678835444

Physical


Approximate Break Strength 4572.21kg (10080 lbs)
 Bale Length 0.254m (10.00")
 Body Style Straight
 Cable Diameter 50.80-63.25mm (2.000-2.490")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Non-magnetic Tin Bronze Wire
 Mesh Length 0.94m (37.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 35444

Reference - Drawing Numbers

Packaging Specification PK-130227-004-001

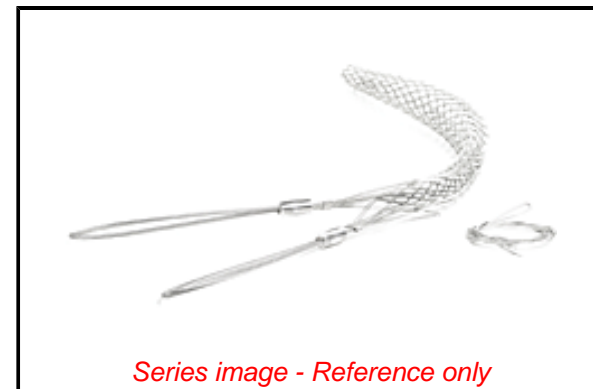

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

130094 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION