

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940523](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 3", Cable Diameter 5.59-8.13mm (.220-.320"), Approximate Break Strength 136.08kg (300 lbs)

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Name	Fiber Optic
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678836671


<b>Physical</b>	
Approximate Break Strength	136.08kg (300 lbs)
Bale Length	0.076m (3.00")
Body Style	Straight
Cable Diameter	5.59-8.13mm (.220-.320")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.064m (2.50")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number 36671

**Reference - Drawing Numbers**

Sales Drawing SD-130094-001-001

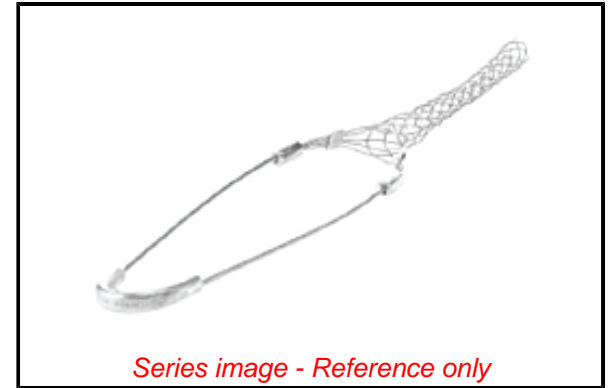

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130094 Series](#)