

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300940529](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Support Grips for Fiber Optics, Closed Mesh, Single Eye, Bale Length 3", Cable Diameter 4.75-6.35mm (.187-.250"), Approximate Break Strength 136.08kg (300 lbs)

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General


Product Family	Cable Grips
Series	130094
Eye Type	Single
O-Ring	N/A
Overview	Support Grips
Product Name	Fiber Optic
Taxonomy	Cable Grips
Type	Support Grip
UPC	78678836680
Physical	
Approximate Break Strength	136.08kg (300 lbs)
Bale Length	0.076m (3.00")
Body Style	Straight
Cable Diameter	4.75-6.35mm (.187-.250")
Color - Grommet	Orange
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.043m (1.70")
Number of Holes	N/A
Thread Size	N/A

Material Info

Engineering Number 36680

Reference - Drawing Numbers

Sales Drawing SD-130094-008-001

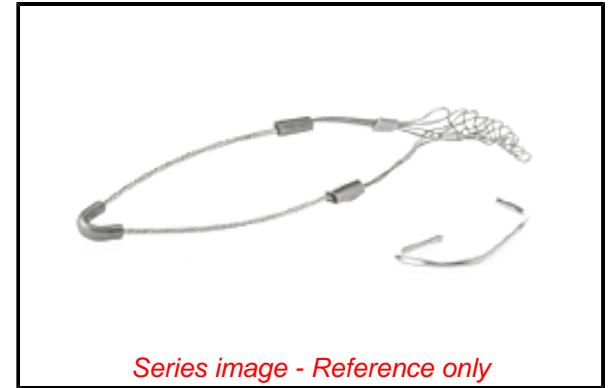

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130094 Series](#)