

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300950242](#)
Status: **Active**
Overview: [Support Grips](#)
Description: Medium Duty Wire Mesh Slack Grip Cable, Split Lace, Double Weave, Offset Eye, Medium Mesh Length 0.432m (17.00"), Approximate Break Strength 1859.73kg (4100 lbs)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family Cable Grips
 Series [130095](#)
 Eye Type Offset
 O-Ring N/A
 Overview [Support Grips](#)
 Product Name Medium Duty
 Taxonomy Cable Grips
 Type Pulling Grip
 UPC 78678836122

Physical


Approximate Break Strength 1859.73kg (4100 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 31.75-37.85mm (1.250-1.490")
 Color - Grommet N/A
 Gender N/A
 Material - Body N/A
 Material - Grip Galvanized Steel
 Mesh Length 0.432m (17.00")
 Number of Holes N/A
 Thread Size N/A

Material Info

Engineering Number 36122

Reference - Drawing Numbers

Sales Drawing SD-130095-114-001

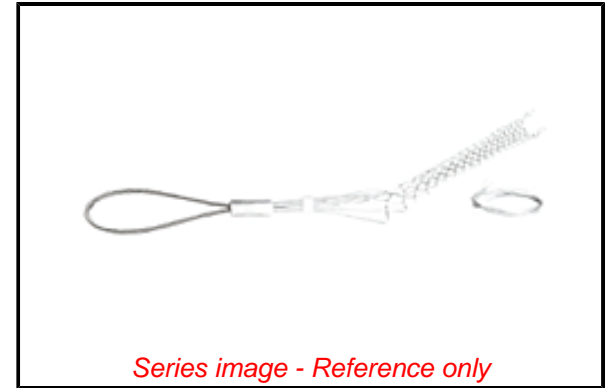

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130095 Series](#)