

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300950257](#)  
**Status:** **Active**  
**Overview:** Support Grips  
**Description:** Medium Duty Wire Mesh Slack Grip Cable, Split Rod, Single Weave, Offset Eye, Medium Mesh Length 0.305m (12.00"), Approximate Break Strength 1859.73kg (4100 lbs)

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159

**General**

Product Family Cable Grips  
 Series [130095](#)  
 Eye Type Offset  
 O-Ring N/A  
 Overview [Support Grips](#)  
 Product Name Medium Duty  
 Taxonomy Cable Grips  
 Type Pulling Grip  
 UPC 78678836143

**Physical**


Approximate Break Strength 1859.73kg (4100 lbs)  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 25.40-31.50mm (1.000-1.240")  
 Color - Grommet N/A  
 Gender N/A  
 Material - Body N/A  
 Material - Grip Galvanized Steel  
 Mesh Length 0.305m (12.00")  
 Number of Holes N/A  
 Thread Size N/A

**Material Info**

Engineering Number 36143

**Reference - Drawing Numbers**

Sales Drawing SD-130095-112-001

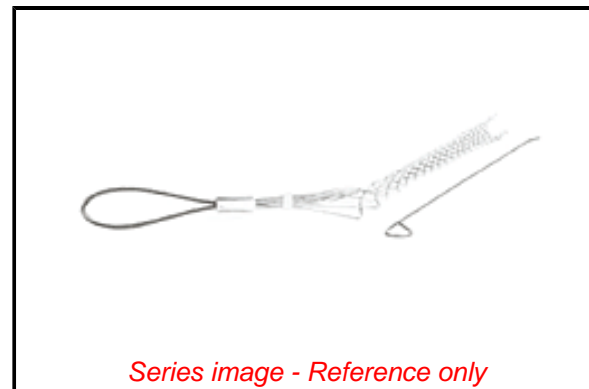

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130095 Series](#)