

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970260](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: Dust-Tight Strain Relief Wide Range Grip, 1/2" NPT, Straight Male, Cable Diameter 10.16-13.72mm (.400-.540"), Approximate Break Strength 167.83kg (370 lbs)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130097](#)
 Eye Type N/A
 Insulated Yes
 NEMA Rating Dust Tight
 O-Ring N/A
 Overview [Strain-Relief Cord Grips](#)
 Product Name Dust-Tight
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678836505
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength 167.83kg (370 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 10.16-13.72mm (.400-.540")
 Color - Grommet N/A
 Gender Male
 Material - Body Zinc Plated Steel
 Material - Grip Galvanized Steel
 Mesh Length 0.152m (6.00")
 Net Weight 53.000/g
 Number of Holes N/A
 Thread Size 1/2" NPT

Material Info

Engineering Number 36505

Reference - Drawing Numbers

Sales Drawing SD-130097-002-001

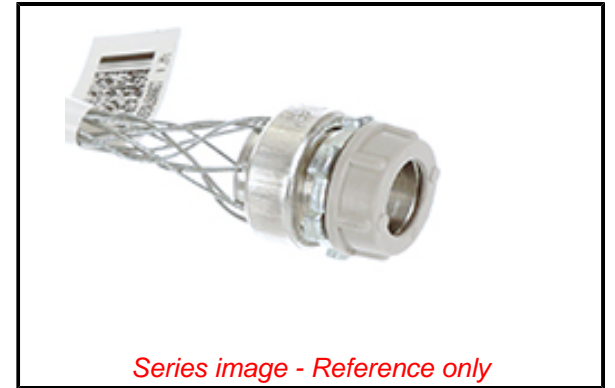

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(b)-II

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[130097 Series](#)