

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300970269](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: Dust-Tight Strain Relief Wide Range Grip, 1-1/4" NPT, Straight Male, Cable Diameter 23.88-31.75mm (.940-1.250"), Approximate Break Strength 317.51kg (700 lbs)

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130097](#)
 Eye Type N/A
 Insulated Yes
 NEMA Rating Dust Tight
 O-Ring N/A
 Overview [Strain-Relief Cord Grips](#)
 Product Name Dust-Tight
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678836515
 Use With 1 1/4" NPT Lock-Nut [1300990146](#)

Physical


Approximate Break Strength 317.51kg (700 lbs)
 Bale Length N/A
 Body Style Straight
 Cable Diameter 23.88-31.75mm (.940-1.250")
 Color - Grommet N/A
 Gender Male
 Material - Body Zinc Plated Steel
 Material - Grip Galvanized Steel
 Mesh Length 0.279m (11.00")
 Number of Holes N/A
 Thread Size 1 1/4" NPT

Material Info

Engineering Number 36515

Reference - Drawing Numbers

Sales Drawing SD-130097-002-001

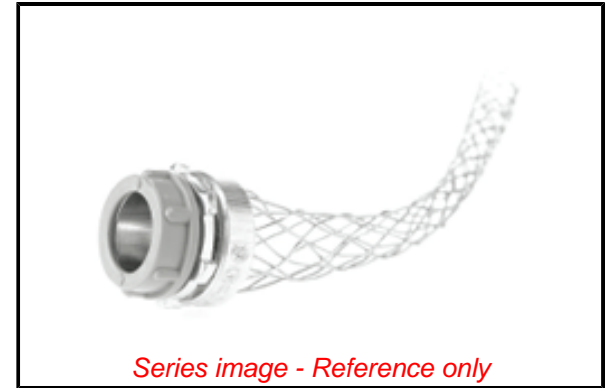

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[130097 Series](#)