

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300970330](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, Straight Male, Cable Diameter 12.70-15.88mm (.500-.625"), Stainless Steel Mesh and Compression Nut

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Grips
Series	<a href="#">130097</a>
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	<a href="#">Strain-Relief Cord Grips</a>
Product Name	MAX-LOC
Taxonomy	Cable Grips
Type	Strain Relief Grip
UPC	78678837140
Use With	3/4" NPT MAX-LOC Lock Nut <a href="#">1300990144</a> , 3/4" NPT MAX-LOC Gasket Sealing Ring <a href="#">1300990150</a> , 3/4" NPT MAX-LOC O-Ring <a href="#">1301800333</a>

**Physical**


Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	12.70-15.88mm (.500-.625")
Color - Grommet	Gray
Gender	Male
Material - Body	Stainless Steel
Material - Grip	Stainless Steel
Mesh Length	N/A
Number of Holes	1
Thread Size	3/4" NPT

**Material Info**

Engineering Number	5538MSS
--------------------	---------

**Reference - Drawing Numbers**

Sales Drawing	SD-130097-102-001
---------------	-------------------

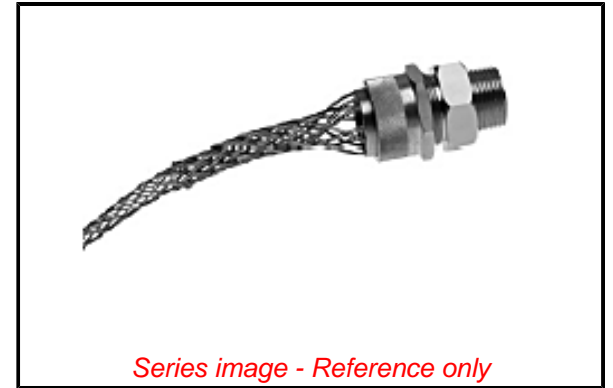

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130097](#) Series