

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980069](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 1/2" NPT, Straight Male, Cable Diameter 9.53-11.10mm (.375-.437")

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130098](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Name MAX-LOC
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678872119
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 9.53-11.10mm (.375-.437")
 Color - Grommet Green
 Gender Male
 Material - Body Nylon
 Material - Grip N/A
 Mesh Length N/A
 Net Weight 28.122/g
 Number of Holes 1
 Thread Size 1/2" NPT

Material Info

Engineering Number 5528

Reference - Drawing Numbers

Sales Drawing 1300980036-000, SD-130098-003-001

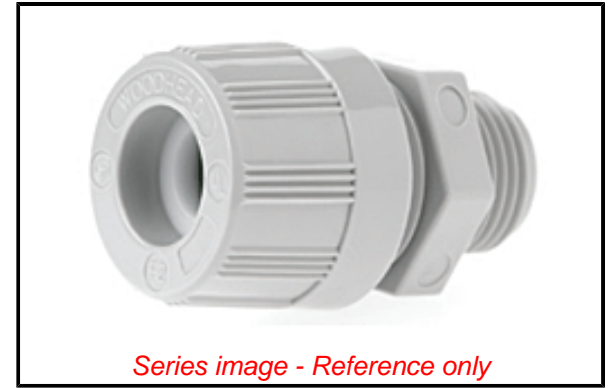

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2020)4578-DC (25
 June 2020)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130098 Series](#)