

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980126](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, Straight Male, Cable Diameter 17.45-20.62mm (.687-.812")

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130098](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Name MAX-LOC
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678872127
 Use With 3/4" NPT MAX-LOC Lock Nut [1300990144](#) , 3/4" NPT MAX-LOC Gasket Sealing Ring [1300990150](#) , 3/4" NPT MAX-LOC O-Ring [1301800333](#)

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 17.45-20.62mm (.687-.812")
 Color - Grommet N/A
 Gender Male
 Material - Body Nylon
 Material - Grip N/A
 Mesh Length N/A
 Net Weight 36.740/g
 Number of Holes 1
 Thread Size 3/4" NPT

Material Info

Engineering Number 5544

Reference - Drawing Numbers

Sales Drawing 1300980235-000

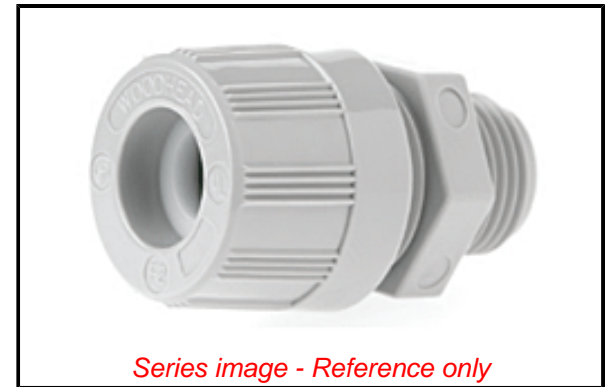

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Relevant

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

[130098 Series](#)