

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300980150](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 1" NPT, Straight Male, Cable Diameter 17.45-20.62mm (.687-.812")

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130098](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Name MAX-LOC
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678872132
 Use With MAX-LOC Lock Nut 1" NPT [1300990145](#) , MAX-LOC Gasket Sealing Ring 1" NPT [1300990151](#) , MAX-LOC O-Ring, 1" NPT [1301800334](#)

Physical


Approximate Break Strength N/A
 Bale Length N/A
 Body Style Straight
 Cable Diameter 17.45-20.62mm (.687-.812")
 Color - Grommet N/A
 Gender Male
 Material - Body Nylon
 Material - Grip N/A
 Mesh Length N/A
 Net Weight 87.960/g
 Number of Holes 1
 Thread Size 1" NPT

Material Info

Engineering Number 5554

Reference - Drawing Numbers

Sales Drawing 1300980132-000

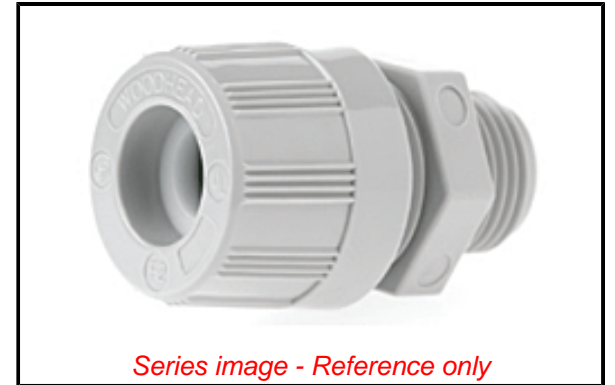

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[130098 Series](#)