

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300980235](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, Straight Male, Cable Diameter 4.75-6.35mm (.187-.250"), with NPT Lock Nut

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR32159  
 UL E76954

**General**

Product Family Cable Grips  
 Series [130098](#)  
 Eye Type N/A  
 NEMA Rating NEMA 3R  
 O-Ring No  
 Overview [Strain-Relief Cord Grips](#)  
 Product Name MAX-LOC  
 Taxonomy Cable Grips  
 Type Strain Relief Grip  
 UPC 78678872100  
 Use With 3/4" NPT MAX-LOC Lock Nut [1300990144](#) , 3/4" NPT MAX-LOC Gasket Sealing Ring [1300990150](#) , 3/4" NPT MAX-LOC O-Ring [1301800333](#)

**Physical**


Approximate Break Strength N/A  
 Bale Length N/A  
 Body Style Straight  
 Cable Diameter 4.75-6.35mm (.187-.250")  
 Color - Grommet Orange  
 Gender Male  
 Material - Body Nylon  
 Material - Grip N/A  
 Mesh Length N/A  
 Net Weight 45.359/g  
 Number of Holes 1  
 Thread Size 3/4" NPT

**Material Info**

Engineering Number 5620

**Reference - Drawing Numbers**

Sales Drawing 1300980235-000, SD-130098-003-001

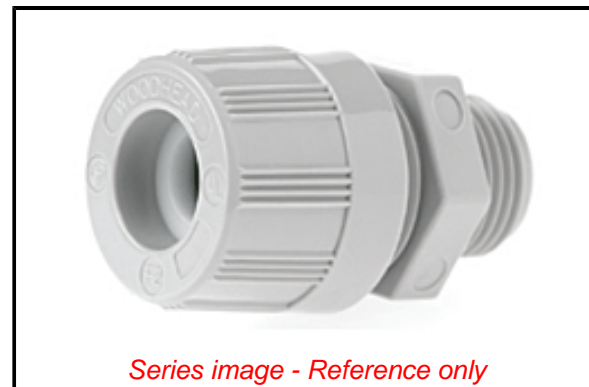

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[130098 Series](#)