

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300990079](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 1/2" NPT, 90° Angle Male, Cable Diameter 7.93-9.53mm (.312-.375"), Non-Metallic Mesh

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159
 UL E76954

General

Product Family Cable Grips
 Series [130099](#)
 Eye Type N/A
 NEMA Rating NEMA 3R
 O-Ring No
 Overview [Strain-Relief Cord Grips](#)
 Product Name MAX-LOC
 Taxonomy Cable Grips
 Type Strain Relief Grip
 UPC 78678855275
 Use With 1/2" NPT MAX-LOC Lock Nut [1300990143](#) , MAX-LOC O-Ring, 1/2" NPT [1301800314](#) , 1/2" NPT MAX-LOC Gasket [1300990149](#)

Physical


Approximate Break Strength 181.44kg (400 lbs)
 Bale Length N/A
 Body Style 90° Angle
 Cable Diameter 7.93-9.53mm (.312-.375")
 Color - Grommet Gray
 Gender Male
 Material - Body Nylon
 Material - Grip Nylon
 Mesh Length 0.102m (4.00")
 Number of Holes 1
 Thread Size 1/2" NPT

Material Info

Engineering Number 5527NM

Reference - Drawing Numbers

Sales Drawing SD-130099-006-001

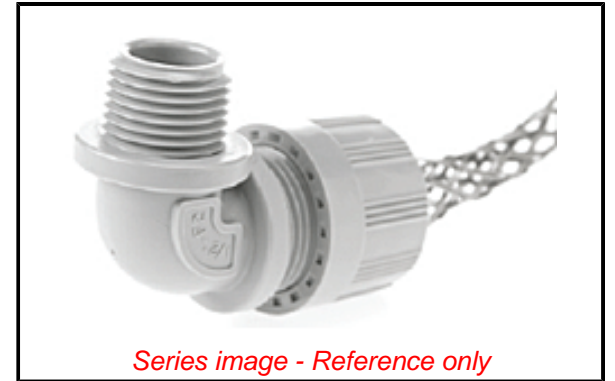

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130099](#) Series