

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300990159](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC Strain Relief Cord-Sealing Grip, 3/4" NPT, 90° Angle Male, Cable Diameter 6.35-9.53mm (.250-.375"), Stainless Steel Mesh

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR32159

General

Product Family	Cable Grips
Series	130099
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	No
Overview	Strain-Relief Cord Grips
Product Name	MAX-LOC
Taxonomy	Cable Grips
Type	Strain Relief Grip
UPC	78678856234
Use With	3/4" NPT MAX-LOC Lock Nut 1300990144 , 3/4" NPT MAX-LOC Gasket Sealing Ring 1300990150 , 3/4" NPT MAX-LOC O-Ring 1301800333

Physical


Approximate Break Strength	226.80kg (500 lbs)
Bale Length	N/A
Body Style	90° Angle
Cable Diameter	6.35-9.53mm (.250-.375")
Color - Grommet	Gray
Gender	Male
Material - Body	Nylon
Material - Grip	Stainless Steel
Mesh Length	0.114m (4.50")
Number of Holes	1
Thread Size	3/4" NPT

Material Info

Engineering Number 5623M

Reference - Drawing Numbers

Sales Drawing SD-130099-004-001

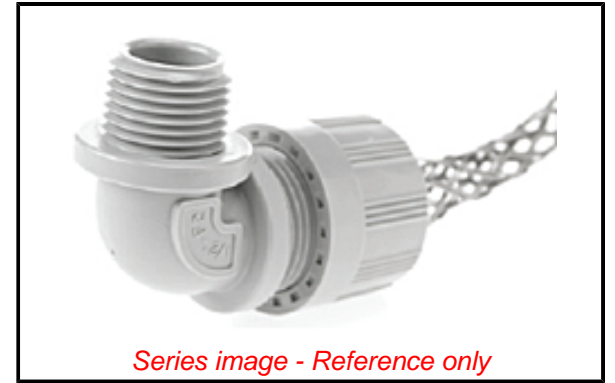

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130099](#) Series