

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300990172](#)  
**Status:** **Active**  
**Overview:** Strain-Relief Cord Grips  
**Description:** MAX-LOC/Watertite Cord Grips, 3/4" NPT, Straight Male, Body Size F3, Cable Diameter 11.10-14.27mm (.437-.562"), Non-Metallic

**Documents:**

[Drawing \(PDF\)](#)  
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable Grips
Series	<a href="#">130099</a>
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	N/A
Overview	<a href="#">Strain-Relief Cord Grips</a>
Product Name	MAX-LOC, Watertite
Taxonomy	Cable Grips
Type	Strain Relief Grip
UPC	78678856335
Use With	3/4" NPT MAX-LOC Lock Nut <a href="#">1300990144</a> , 3/4" NPT MAX-LOC Gasket Sealing Ring <a href="#">1300990150</a> , 3/4" NPT MAX-LOC O-Ring <a href="#">1301800333</a>

**Physical**


Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	11.10-14.27mm (.437-.562")
Color - Grommet	N/A
Gender	Male
Material - Body	Nylon
Material - Grip	Nylon
Mesh Length	N/A
Number of Holes	1
Thread Size	3/4" NPT

**Material Info**

Engineering Number	5633NM
--------------------	--------

**Reference - Drawing Numbers**

Sales Drawing	SD-130099-008-001
---------------	-------------------

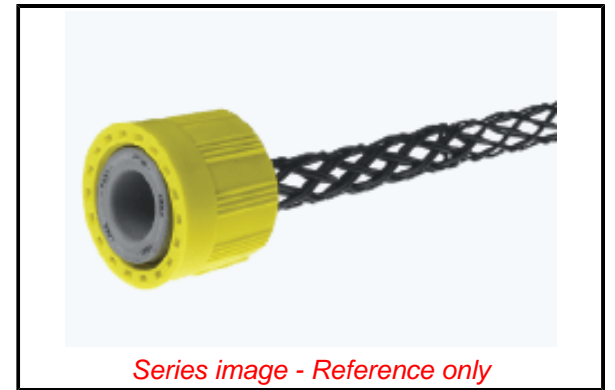

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130099 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**