

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300990174](#)
Status: **Active**
Overview: Strain-Relief Cord Grips
Description: MAX-LOC/Watertite Cord Grips, 3/4" NPT, Straight Male, Body Size F3, Cable Diameter 12.70-15.88mm (.500-.625"), Non-Metallic

Documents:

[Drawing \(PDF\)](#)
[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Grips
Series	130099
Eye Type	N/A
NEMA Rating	NEMA 3R
O-Ring	N/A
Overview	Strain-Relief Cord Grips
Product Name	MAX-LOC, Watertite
Taxonomy	Cable Grips
Type	Strain Relief Grip
UPC	78678872220
Use With	3/4" NPT MAX-LOC Lock Nut 1300990144 , 3/4" NPT MAX-LOC Gasket Sealing Ring 1300990150 , 3/4" NPT MAX-LOC O-Ring 1301800333

Physical


Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	12.70-15.88mm (.500-.625")
Color - Grommet	N/A
Gender	Male
Material - Body	Nylon
Material - Grip	Nylon
Mesh Length	N/A
Number of Holes	1
Thread Size	3/4" NPT

Material Info

Engineering Number	5634NM
--------------------	--------

Reference - Drawing Numbers

Sales Drawing	SD-130099-008-001
---------------	-------------------

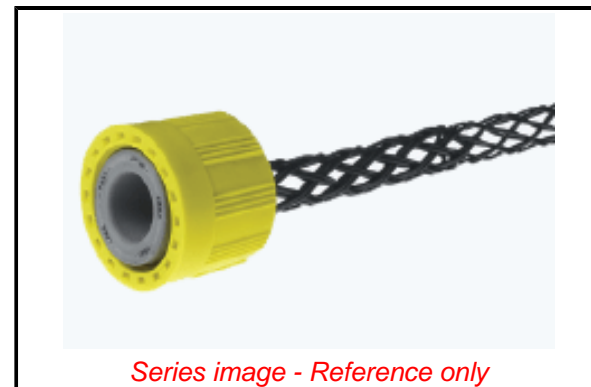

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130099 Series](#)