

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301020253](#)
Status: **Active**
Overview: [Hand Lamps](#)
Description: Safeway Phenolic Hand Lamp with 100W, Screw Release Guard with Reflector, with Switch, Cord Type 16/3 SJTOW, Cord Length 7.62m (25.0')

Documents:

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR85374

General

Product Family Portable Lighting
 Series [130102](#)
 NEMA Configuration NEMA 5-15
 Outlet None
 Overview [Hand Lamps](#)
 Product Name Safety Yellow
 Taxonomy Lamps and Lights
 Type Hand Lamps
 UPC 78678879524

Physical


Cord Length - Primary 7.62m (25.0')
 Cord Length - Secondary N/A
 Depth 101.60mm (4.000")
 Duty Commercial
 Guard Included Yes
 Guard Type Reflector, Screw Release
 Height 381.00mm (15.000")
 Length N/A
 Material - Guard #8 Gauge Zinc-plated Steel
 Mounting Style Hand Held
 Packaging Type Carton
 Socket Construction N/A

Electrical

Bulb Type Incandescent
 Cord Type - Primary 16/3 SJTOW
 Lamp Type A21
 Lamp Wattage - Maximum 100W
 Lumens 1000
 On/Off Switch Yes
 Voltage (Fixture) - Maximum 240V

Material Info

Engineering Number 271SA163

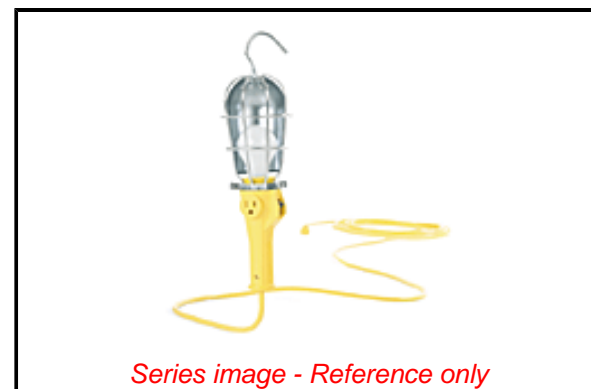

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130102 Series](#)