

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301100050](#)
Status: **Active**
Overview: Wide-Area Lighting Products
Description: Pro-Yellow 400W Metal Halide High Bay Light with Lamp Molded 18/3 SJTW 1.83m (6.0') Pulse Start

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

UL E174253

General

Product Family Portable Lighting
 Series [130110](#)
 NEMA Configuration NEMA 5-15
 NEMA Rating Rain Tight
 Outlet None
 Overview Wide-Area Lighting Products
 Product Name Pro-Yellow
 Taxonomy Lamps and Lights
 Type Wide Area Lamps
 UPC 78172505741

Physical

Cord Length - Primary 0.91m (3.0')
 Cord Length - Secondary N/A
 Depth N/A
 Duty General
 Guard Included Yes
 Guard Type Steel
 Height 463.55mm (18.250")
 Length N/A
 Material - Guard #10 Gauge Zinc-plated Steel
 Mounting Style Hook
 Net Weight 6477.293/g
 Packaging Type Carton
 Socket Construction N/A

Electrical


Bulb Type Metal Halide - Pulse Start
 Cord Type - Primary 16/3 SOOW
 Lamp Type BT37/ED-37 Type O
 Lamp Wattage - Maximum 400W
 Lumens 26000
 On/Off Switch No
 Voltage (Fixture) - Maximum 120VAC 60 HZ

Material Info

Engineering Number 8575-MH-PS

Reference - Drawing Numbers

Sales Drawing SD-130110-002-001

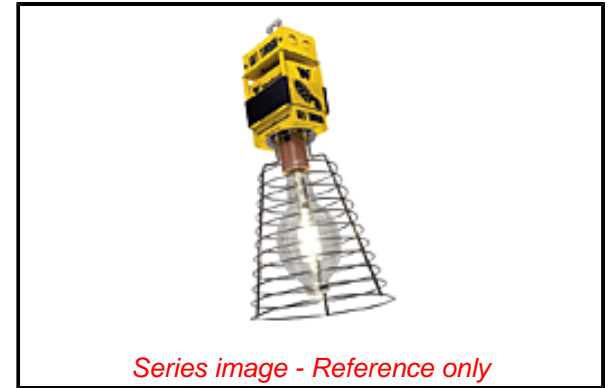

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130110 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION