

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460015](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: Watertite Extreme Plug, 3 Pole/3 Wire, Non-NEMA, 15A/125V, 10A/250V, Cord Grip Body Size F2, Silicone Husk

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837

General

| | |
|--------------------|---|
| Product Family | Wiring Devices |
| Series | 130146 |
| IP Rating | IP69K |
| NEMA Configuration | Non-NEMA |
| Overview | Watertite Extreme Wet-Location Wiring Solutions |
| Product Name | Watertite Extreme |
| Receptacle Type | N/A |
| Specialty | N/A |
| Taxonomy | Wiring Devices |
| Type | Plug |
| UPC | 78678871080 |

Physical

| | |
|---------------------|---------------|
| Cord Grip Body Size | F2 1/2" |
| Flange | No |
| Flip Lid | No |
| Gender | Male |
| Length | N/A |
| Locking Blade | No |
| Net Weight | 126.098/g |
| Poles | 3-pole/3-wire |

Electrical


| | |
|-------------------------------|-------|
| Cord Type | N/A |
| Current - Maximum per Contact | 15.0A |
| GFCI | No |
| Lighted Connector | No |
| Voltage - Maximum | 250V |

Material Info

Engineering Number 14W07

Reference - Drawing Numbers

Sales Drawing 1301460015-000

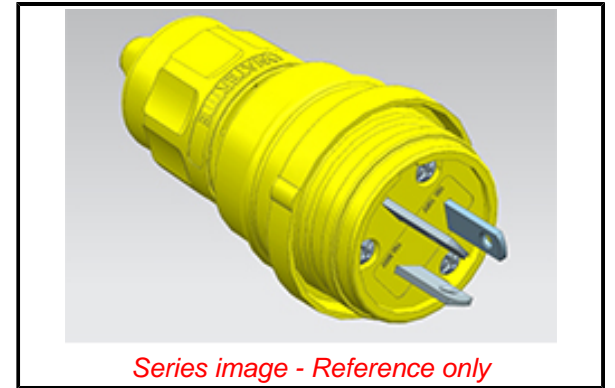

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Relevant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)