

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460041](#)

Status: **Active**

Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)

Description: Watertite Extreme Extra Hard Outdoor Plug, 2 Pole/3 Wire, NEMA 6-20, 250V, Cord Grip Body Size F2, Black, Silicone Husk

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E10176

General

Product Family Wiring Devices
Series [130146](#)
IP Rating IP69K
NEMA Configuration NEMA 6-20
Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
Product Name Watertite Extreme
Receptacle Type N/A
Specialty N/A
Taxonomy Wiring Devices
Type Plug
UPC 78678871049

Physical

Cord Grip Body Size F2 1/2"
Flange No
Flip Lid No
Gender Male
Length N/A
Locking Blade No
Poles 2-pole/3-wire

Electrical


Cord Type N/A
Current - Maximum per Contact 20.0A
GFCI No
Lighted Connector No
Voltage - Maximum 250V

Material Info

Engineering Number 14W48BLK

Reference - Drawing Numbers

Sales Drawing 1301460040-000

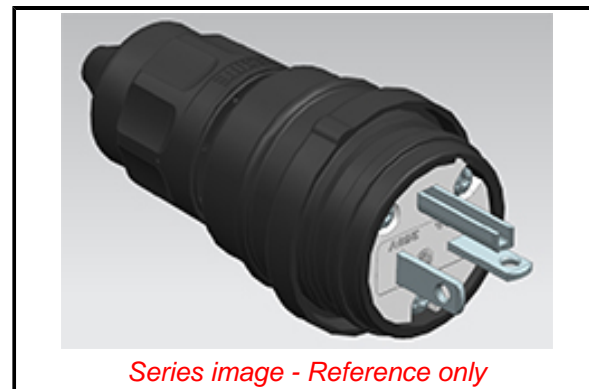

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130146 Series](#)