

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301460054](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Ground Fault Monitoring Connector 2 Pole/3 Wire, NEMA 5-20, 125V, Cord Grip Body Size F2, Silicone Husk

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Datasheet \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family Wiring Devices  
 Series [130146](#)  
 IP Rating IP69K  
 NEMA Configuration NEMA 5-20  
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)  
 Product Name Watertite Extreme  
 Receptacle Type Single  
 Specialty Monitoring  
 Taxonomy Wiring Devices  
 Type Connector  
 UPC 78678805847

**Physical**

Cord Grip Body Size F2 1/2"  
 Flange No  
 Flip Lid No  
 Gender Female  
 Length N/A  
 Locking Blade No  
 Poles 2-pole/3-wire

**Electrical**


Cord Type N/A  
 Current - Maximum per Contact 20.0A  
 GFCI No  
 Lighted Connector Yes  
 Voltage - Maximum 125V

**Material Info**

Engineering Number 15W33GCM

**Reference - Drawing Numbers**

Sales Drawing 1301460054-000

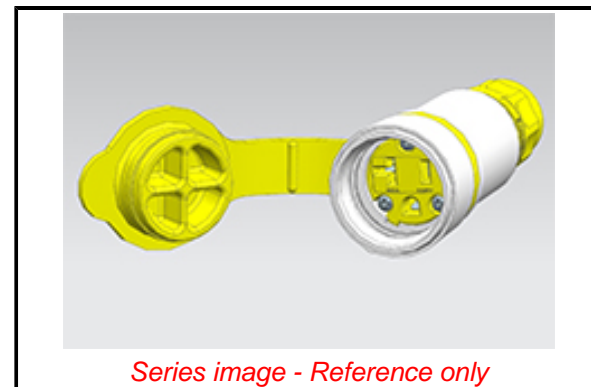

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130146 Series](#)