

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460106](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: [Watertite Extreme Connector with Locking Blade, 2 Pole/3 Wire, NEMA L6-15, 250V, Cord Grip Body Size F2, Silicone Husk](#)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family [Wiring Devices](#)
 Series [130146](#)
 IP Rating [IP69K](#)
 NEMA Configuration [NEMA L6-15](#)
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
 Product Name [Watertite Extreme](#)
 Receptacle Type [Single](#)
 Specialty [N/A](#)
 Taxonomy [Wiring Devices](#)
 Type [Connector](#)
 UPC [78678870086](#)

Physical

Cord Grip Body Size [F2 1/2"](#)
 Flange [No](#)
 Flip Lid [No](#)
 Gender [Female](#)
 Length [N/A](#)
 Locking Blade [Yes](#)
 Net Weight [190.508/g](#)
 Poles [2-pole/3-wire](#)

Electrical


Cord Type [N/A](#)
 Current - Maximum per Contact [15.0A](#)
 GFCI [No](#)
 Lighted Connector [No](#)
 Voltage - Maximum [250V](#)

Material Info

Engineering Number [25W49](#)

Reference - Drawing Numbers

Sales Drawing [1301460106-000](#)

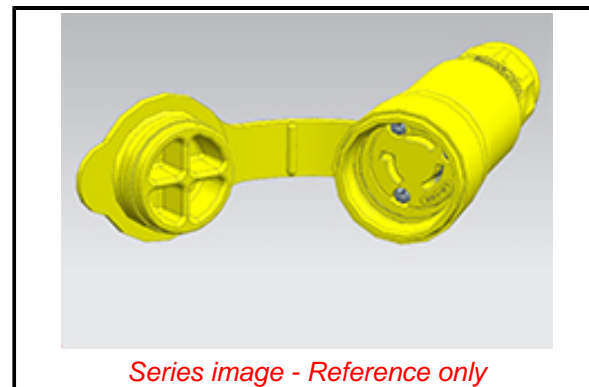

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130146 Series](#)