

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301460146](#)
Status: **Active**
Overview: Watertite Extreme Wet-Location Wiring Solutions
Description: Watertite Extreme Receptacle Duplex Flip Coverplate with Locking Blade, 3 Pole/3 Wire, Non-NEMA 15A/125V, 10A/250V

Documents:

3D Model	Brochure (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
3D Model (PDF)	

Agency Certification

CSA	LR6837
UL	E68122

General

Product Family	Wiring Devices
Series	130146
IP Rating	IP67
NEMA Configuration	Non-NEMA Locking
Overview	<u>Watertite Extreme Wet-Location Wiring Solutions</u>
Product Name	Watertite Extreme
Receptacle Type	Duplex
Specialty	N/A
Taxonomy	Wiring Devices
Type	Receptacle
UPC	78678871441

Physical

Flange	No
Flip Lid	Yes
Gender	Female
Length	N/A
Locking Blade	Yes
Poles	3-pole/3-wire

Electrical


Cord Type	N/A
Current - Maximum per Contact	10.0A, 15.0A
GFCI	No
Lighted Connector	No
Voltage - Maximum	125V / 250V

Material Info

Engineering Number	65W07DPLX
--------------------	-----------

Reference - Drawing Numbers

Sales Drawing	1301460146-000
---------------	----------------

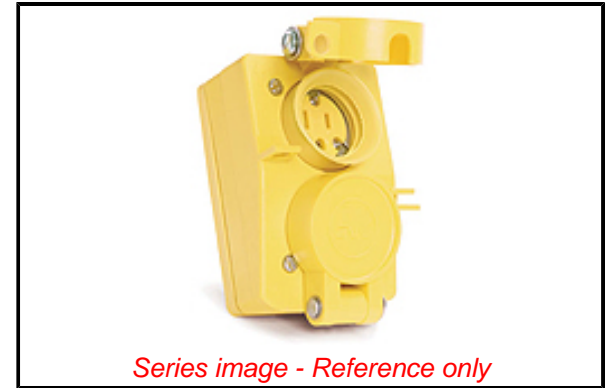

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

China RoHS

Search Parts in this Series

[130146 Series](#)