

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301470061](#)
Status: **Active**
Overview: [Watertite Extreme Wet-Location Wiring Solutions](#)
Description: [Watertite Extreme Connector for Male Receptacle with Locking Blade, Single Flip Coverplate, 3 Pole/4 Wire, NEMA L16-20, 3ø 250V, F3](#)

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Brochure \(PDF\)](#)

Agency Certification

CSA LR6837

General

Product Family [Wiring Devices](#)
Series [130147](#)
IP Rating [IP67](#)
NEMA Configuration [NEMA L16-20](#)
Overview [Watertite Extreme Wet-Location Wiring Solutions](#)
Product Name [Watertite Extreme](#)
Receptacle Type [Single](#)
Specialty [N/A](#)
Taxonomy [Wiring Devices](#)
Type [Connector](#)
UPC [78678871374](#)

Physical

Cord Grip Body Size [F3 3/4"](#)
Flange [No](#)
Flip Lid [No](#)
Gender [Female](#)
Length [N/A](#)
Locking Blade [Yes](#)
Net Weight [242.671/g](#)
Poles [3-pole/4-wire](#)

Electrical


Cord Type [N/A](#)
Current - Maximum per Contact [20.0A](#)
GFCI [No](#)
Lighted Connector [No](#)
Voltage - Maximum [3ø 250V](#)

Material Info

Engineering Number [27W76MB](#)

Reference - Drawing Numbers

Sales Drawing [1301470061-000](#)

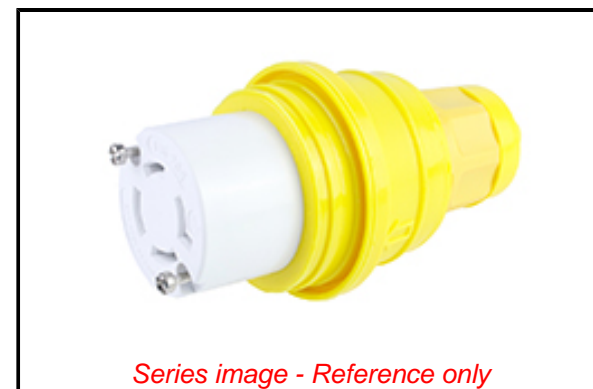

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[130147 Series](#)