

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301470089](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Connector with Locking Blade, 3 Pole/3 Wire, Non-NEMA, 250V, Cord Grip Body Size F4

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Brochure \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family Wiring Devices  
 Series [130147](#)  
 IP Rating IP67  
 NEMA Configuration Non-NEMA Locking  
 Overview [Watertite Extreme Wet-Location Wiring Solutions](#)  
 Product Name Watertite Extreme  
 Receptacle Type Single  
 Specialty N/A  
 Taxonomy Wiring Devices  
 Type Connector  
 UPC 78678871392

**Physical**

Cord Grip Body Size F4 1"  
 Flange No  
 Flip Lid No  
 Gender Female  
 Length N/A  
 Locking Blade Yes  
 Net Weight 391.903/g  
 Poles 3-pole/3-wire

**Electrical**


Cord Type N/A  
 Current - Maximum per Contact 30.0A  
 GFCI No  
 Lighted Connector No  
 Voltage - Maximum 250V

**Material Info**

Engineering Number 29W08

**Reference - Drawing Numbers**

Sales Drawing 1301470089-000

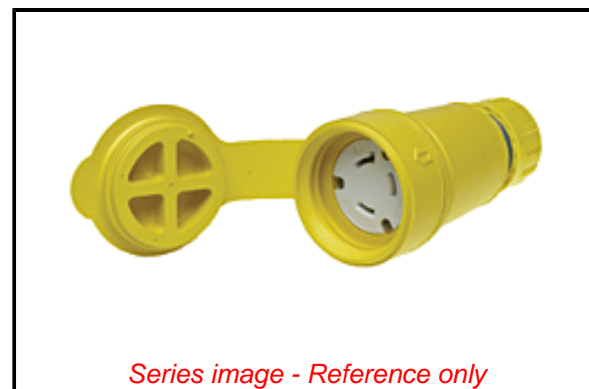

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**Search Parts in this Series**

[130147 Series](#)