

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301490012](#)  
**Status:** **Active**  
**Overview:** [Heavy-Duty Industrial Wiring Devices](#)  
**Description:** Safeway Flanged Receptacle, 2 Pole/3 Wire, NEMA 5-15, 125V

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E46237

**General**

Product Family [Wiring Devices](#)  
 Series [130149](#)  
 IP Rating N/A  
 NEMA Configuration NEMA 5-15  
 Overview [Heavy-Duty Industrial Wiring Devices](#)  
 Product Name Safeway  
 Receptacle Type Single  
 Specialty N/A  
 Taxonomy [Wiring Devices](#)  
 Type Receptacle  
 UPC 78678870314

**Physical**


Flange Yes  
 Flip Lid No  
 Gender Female  
 Length N/A  
 Locking Blade No  
 Poles 2-pole/3-wire

**Electrical**

Cord Type N/A  
 Current - Maximum per Contact 15.0A  
 GFCI No  
 Lighted Connector No  
 Voltage - Maximum 125V

**Material Info**

Engineering Number 1547MB

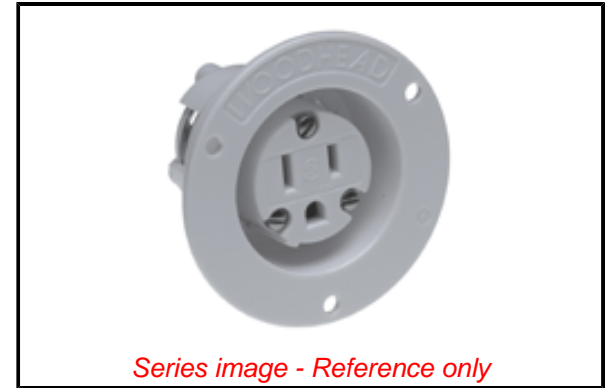

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Relevant**

**REACH SVHC**

Not Relevant

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

**Search Parts in this Series**

[130149 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**