

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301500206](#)  
**Status:** **Active**  
**Overview:** [Heavy-Duty Industrial Wiring Devices](#)  
**Description:** 60 Amp Safeway Pin and Sleeve Receptacle with Flip Lid, 3 Pole/4 Wire, 250V, Orange

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E145923

**General**

Product Family [Wiring Devices](#)  
 Series [130150](#)  
 Comments [IEC Configuration 309-1/309-2](#)  
 IP Rating [IP44](#)  
 NEMA Configuration [N/A](#)  
 Overview [Heavy-Duty Industrial Wiring Devices](#)  
 Product Name [Safeway](#)  
 Receptacle Type [Single](#)  
 Specialty [Pin and Sleeve](#)  
 Taxonomy [Wiring Devices](#)  
 Type [Receptacle](#)  
 UPC [78678872494](#)

**Physical**

Flange [Yes](#)  
 Flip Lid [Yes](#)  
 Gender [Female](#)  
 Length [N/A](#)  
 Locking Blade [No](#)  
 Poles [3-pole/4-wire](#)

**Electrical**


Cord Type [N/A](#)  
 Current - Maximum per Contact [60.0A](#)  
 GFCI [No](#)  
 Lighted Connector [No](#)  
 Voltage - Maximum [250V](#)

**Material Info**

Engineering Number [460R12](#)

**Reference - Drawing Numbers**

Sales Drawing [1301500058-000](#)

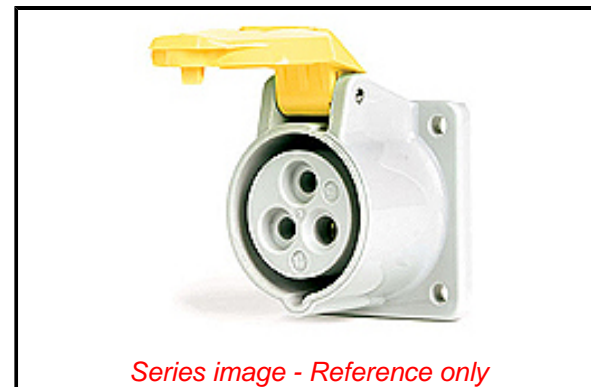

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

**China RoHS**

**Search Parts in this Series**

[130150 Series](#)