

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301540049](#)  
**Status:** **Active**  
**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Inline GFCI Molded Y Cordset, 2 Pole/3 Wire, Cordset Length 0.91m (3.0'), NEMA 5-15, 125V

**Documents:**

[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Wiring Devices
Series	<a href="#">130154</a>
IP Rating	IP67
NEMA Configuration	NEMA 5-15
Overview	<a href="#">Watertite Extreme Wet-Location Wiring Solutions</a>
Product Name	Watertite Extreme
Receptacle Type	Duplex
Specialty	N/A
Taxonomy	Wiring Devices
Type	Molded Y Cordset
UPC	78678835612

**Physical**


Cord Grip Body Size	F2 1/2"
Flange	No
Flip Lid	No
Gender	Male-Female
Length	0.91m (3.0')
Locking Blade	No
Poles	2-pole/3-wire

**Electrical**

Cord Type	12/3 SJOW
Current - Maximum per Contact	15.0A
GFCI	Yes-In-line
Lighted Connector	No
Voltage - Maximum	125V

**Material Info**

Engineering Number	14W47-Y-IN
--------------------	------------

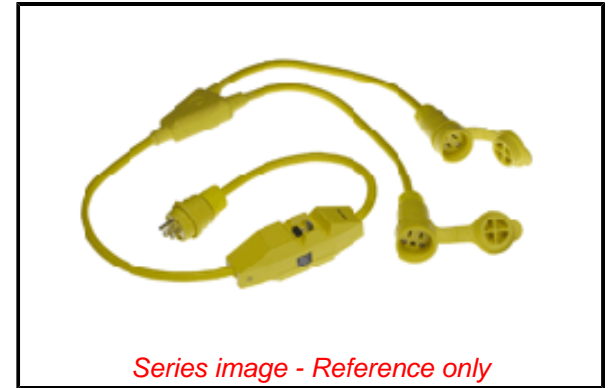

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

**China RoHS**

**Search Parts in this Series**

[130154 Series](#)