

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301550141](#)

**Status:** **Active**

**Overview:** [Watertite Extreme Wet-Location Wiring Solutions](#)

**Description:** Watertite Extreme Connector with California Style Locking Blade, 3 Pole/4 Wire, Non-NEMA, 50A/125V/250V, Cord Grip Body Size F5

**Documents:**

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
UL E10176

**General**

Product Family Wiring Devices  
Series [130155](#)  
IP Rating IP67  
NEMA Configuration Non-NEMA Locking CA  
Overview [Watertite Extreme Wet-Location Wiring Solutions](#)  
Product Name Watertite Extreme  
Receptacle Type Single  
Specialty N/A  
Taxonomy Wiring Devices  
Type Connector  
UPC 78678801470

**Physical**


Cord Grip Body Size F5 1 1/4"  
Flange No  
Flip Lid No  
Gender Female  
Length N/A  
Locking Blade Yes  
Net Weight 773.827/g  
Poles 3-pole/4-wire

**Electrical**

Cord Type N/A  
Current - Maximum per Contact 50.0A  
GFCI No  
Lighted Connector No  
Voltage - Maximum 250V

**Material Info**

Engineering Number CS63W64

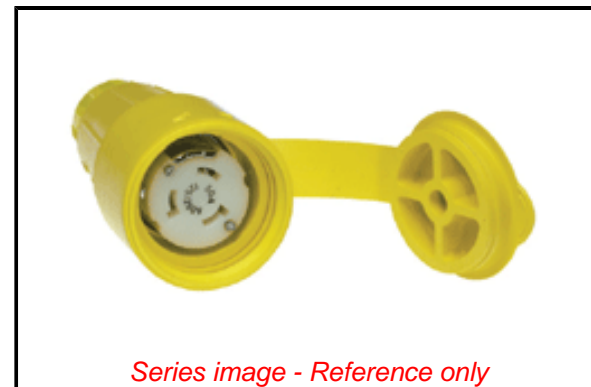

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Relevant**

**REACH SVHC**

Not Relevant

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

**Search Parts in this Series**

[130155 Series](#)