


REV. 0
DCO 170339

COIL: @ 25°C	
RESISTANCE	5000 OHMS ± 10%
NOMINAL VOLTAGE	6.0 mADC
MUST OPERATE	2.8 mADC
MUST RELEASE	1.4 mADC MAX, 0.3 mADC MIN

ENVIRONMENT:	
VIBRATION	10 CPS TO 2000 CPS @ 15 g's
SHOCK	100 g's 6 MS DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.
RELEASE TIME 10 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

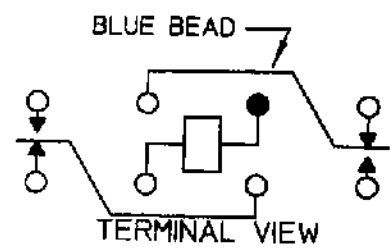

CONTACT RATING: 2 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. PBB 12/6/00 CK. TLG 12-6-00



CUST. QPL	3SAT RELAY
CUST. NO. M5757/13-090 REV.	

BSAT1307A2